



SIEMENS

www.siemens.com/diagnostics

Standardize your test results
with trusted urinalysis technology
that maximizes productivity.


CLINITEK Novus Analyzer

Answers for life.

Improve Reliability and Productivity

with the urinalysis technology you trust.

CLINITEK Novus™ Automated Urine Chemistry Analyzer† combines proven dry-pad urine chemistry technology with an easy-to-use cassette test format to ensure standardized test results and maximum productivity in busy laboratories. Offering a full spectrum of tests and a throughput of up to 240 samples per hour, the CLINITEK Novus analyzer streamlines workflow, simplifies routine urinalysis and STAT testing, and delivers consistent, high-quality results, even during peak periods.

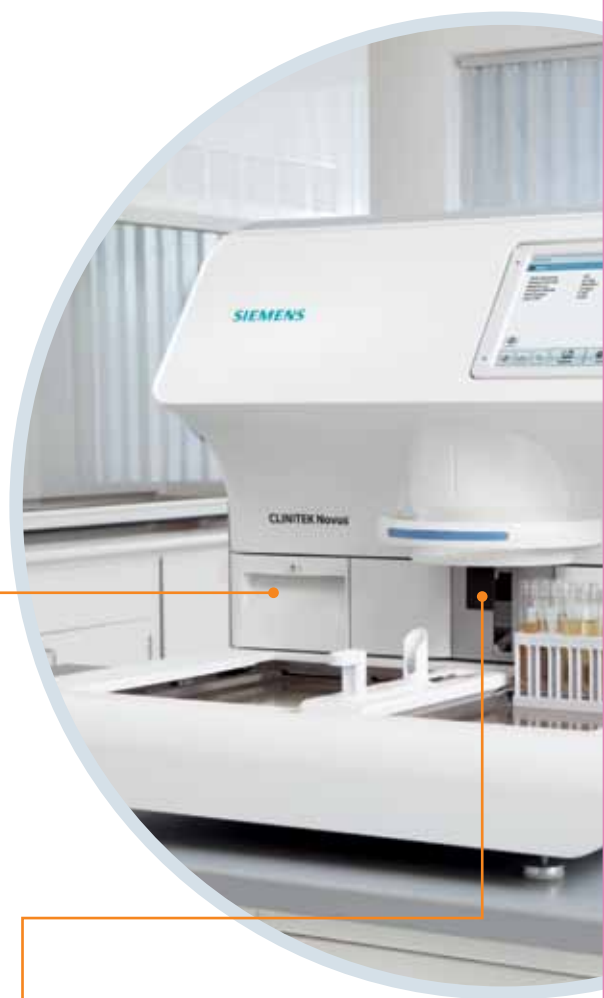

Unique 'load-and-go' test cassettes

- Each cassette holds 450 test sets
- Easy-to-use cassettes simplify analyzer operation, maintenance, and cleaning
- Proven test pads ensure quality results with excellent sensitivity and specificity
- Cassettes eliminate the need to orient traditional urinalysis test strips

Broadest menu

- CLINITEK Novus 10 cassettes for routine urinalysis
- CLINITEK Novus PRO 12 cassettes for early detection of kidney disease
- Albumin-to-Creatinine (A:C) ratio results for microalbuminuria testing



True calibration of all analytes

- Live calibration ensures confidence in results
- Ready-to-use liquid calibration material enhances accuracy

**Proven Performance in Urinalysis—
from the Point-of-Care to the Central Lab**

CLINITEK® urine analyzers from Siemens Healthcare Diagnostics employ the same proven testing technology, regardless of the test format. That's why you can be sure of standardized test results in every setting, from Point-of-Care locations to the high-volume automated laboratory. The CLINITEK brand remains recognized the world over as the leader in reliable urine chemistry testing—meeting the needs of different patient populations, enhancing productivity, and providing broad clinical insights into patient health.

CLINITEK Novus 10 cassette tests¹

Glucose

Bilirubin

Ketone

Blood

pH

Protein

Urobilinogen

Nitrite

Leukocytes

CLINITEK Novus PRO 12 cassette tests¹

All Novus 10 tests, plus:

Albumin

Creatinine

Albumin-to-Creatinine Ratio

Protein-to-Creatinine Ratio

1. Specific Gravity, Color, and Clarity are also analyzed.



Tiltable color touch screen

- Intuitive navigation through a logical menu
- Flexible menu options for easy system customization, setup, maintenance, QC, and troubleshooting



Load up to 200 samples at one time

- Maximize productivity with true walkaway functionality
- Wide range of testing volumes and tube sizes
- Liquid-level sensing speeds and simplifies sample preparation
- Tube Imaging Library identifies tube and presence/absence of cap to ensure pipette reliability
- Rack handler is compatible with Sysmex® UF-1000i automated sediment analyzer for easy manual transfers[‡]



Convenient, onboard barcode data entry

- Minimizes data entry errors and improves traceability
- Automated entry of lot number and expiration via RFID tag

† Not available for sale in the U.S.

‡ Not available in all countries.

Siemens Healthcare Diagnostics, a global leader in clinical diagnostics, provides healthcare professionals in hospital, reference, and physician office laboratories and point-of-care settings with the vital information required to accurately diagnose, treat, and monitor patients. Our innovative portfolio of performance-driven solutions and personalized customer care combine to streamline workflow, enhance operational efficiency, and support improved patient outcomes.

CLINITEK Novus and all associated marks are trademarks of Siemens Healthcare Diagnostics Inc. All other trademarks and brands are the property of their respective owners. Product availability may vary from country to country and is subject to varying regulatory requirements. Please contact your local representative for availability.

Order No. A91DX-120998-GC1-4A00
01-2012 | All rights reserved
© 2012 Siemens Healthcare Diagnostics Inc.

Global Siemens Headquarters

Siemens AG
Wittelsbacherplatz 2
80333 Muenchen
Germany

**Global Siemens Healthcare
Headquarters**

Siemens AG
Healthcare Sector
Henkestrasse 127
91052 Erlangen
Telephone: +49 9131 84-0
Germany
www.siemens.com/healthcare

Global Division

Siemens Healthcare Diagnostics Inc.
511 Benedict Avenue
Tarrytown, NY 10591-5005
USA
www.siemens.com/diagnostics